

# Fact Sheet

## BHA® Replacement Cartridge Filter for Camfil Gold Series X-Flo

### Key Benefits


- Stiffer, heavier gauge sheet metal top pan to resist bowing
- More conventional design: no inner conical filter, greater pleat depth on cylindrical filter
- Wider gasket contact area than OEM filter for better sealing

### Performance Data and Filter Facts:

- Rated airflow: up to 1500 cfm per filter
- Filter media surface area: up to 350 ft<sup>2</sup> / 32.5 m<sup>2</sup>
- 1.88" pleat depth
- Temperature rating (continuous), all medias: 200°F / 93°C

### Filter Construction:

- Dimensions: 16" OD x 11.5" ID x 39" height
- 17 3/4" x 21" top pan, 14 gauge galvanized steel
- 16" OD bottom pan, 18 gauge galvanized steel
- Galvanized expanded metal core
- 5/16" x 1/2" EPDM/Neoprene sponge gasket
- Four 1" wide reinforcement straps
- Urethane potting compound

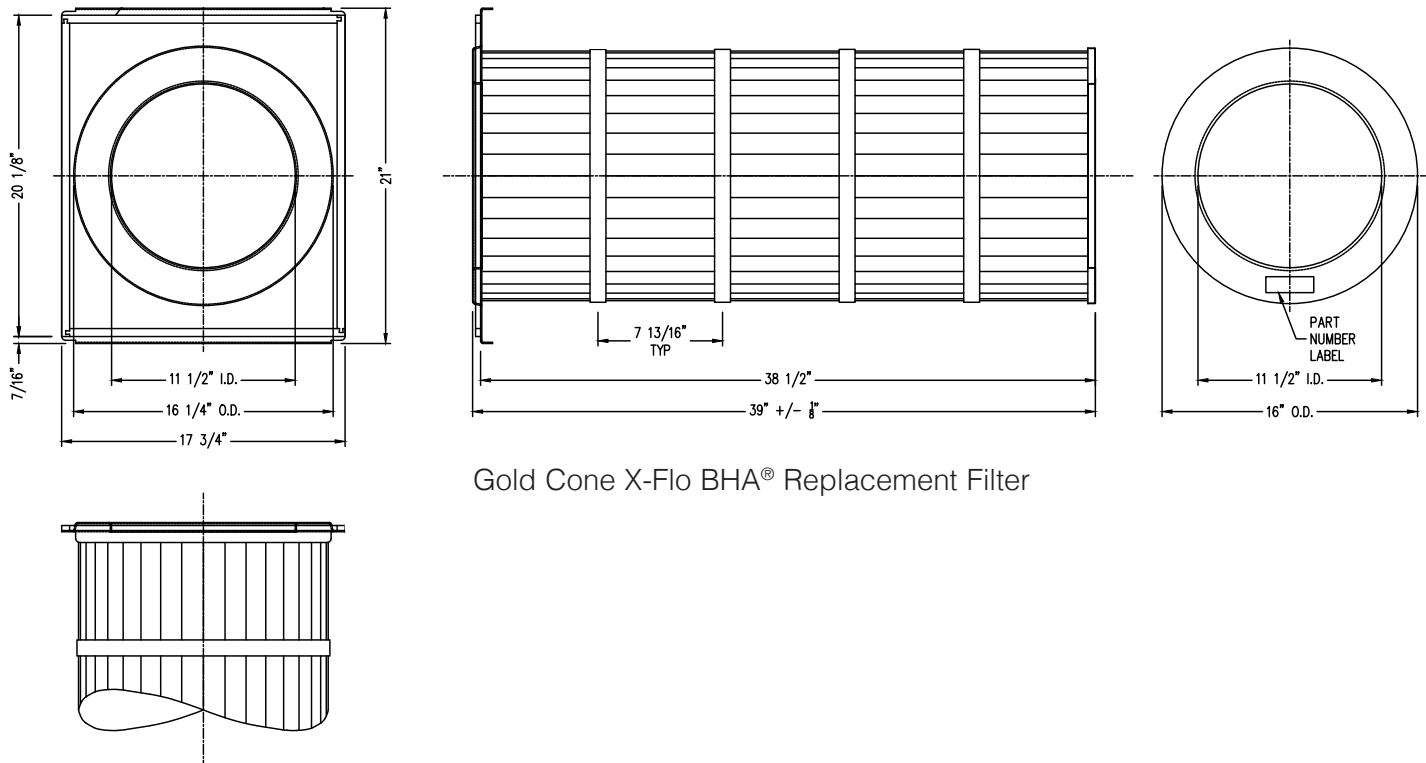

Gold Cone X-Flo BHA® Replacement Filter



# Fact Sheet

## BHA® Replacement Cartridge Filter for Camfil Gold Series X-Flo

### Available Medias and ASHRAE 52.2 Efficiency Rating:

- MERV 10 cellulose/synthetic blend
- MERV 15 BHA ProTura® Advanced Nanofiber cellulose/synthetic blend
- MERV 15 BHA ProTura® SB Advanced Nanofiber polyester non-woven
- MERV 16 BHA Preveil® Membrane laminated to spunbond polyester

### Available Media Finishes:

- Hydrophobic
- Fire Retardant
- Carbon Impregnated



*Gold Series X-Flo is a registered trademark of Camfil Farr, Inc.*

