

Ordering Information

C
Cover

Nominal Size

A
Cover with X-Connection and Gauge Port G1/4"

A
Without Auxiliary Function

Orifice

Seals

Design Series not required for ordering

 
Code	Description
016	NG16
025	NG25
032	NG32
040	NG40
050	NG50
063	NG63
080	NG80
100	NG100

Code	Description
N	Nitrile
V	Fluorocarbon

Code	Description
99	Without Orifice, Open Orifice Options

Weight:

C016A	0.9 kg (2.0 lbs.)
C025A	1.9 kg (4.2 lbs.)
C032A	2.9 kg (6.4 lbs.)
C040A	5.3 kg (11.7 lbs.)
C050A	8.5 kg (18.7 lbs.)
C063A	15.5 kg (34.2 lbs.)
C080A	34.0 kg (75.0 lbs.)
C100A	58.0 kg (127.9 lbs.)





○ Orifice position

For orifice recommendations, bolt and seal kits, see Accessories.



Dimensions

Inch equivalents for millimeter dimensions are shown in (**)

NG16 to NG63

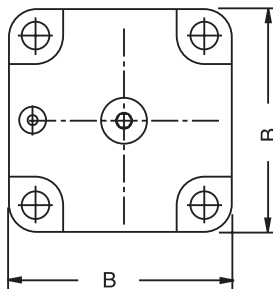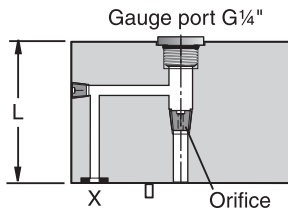

NG80 to NG100

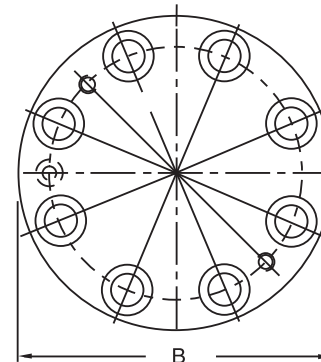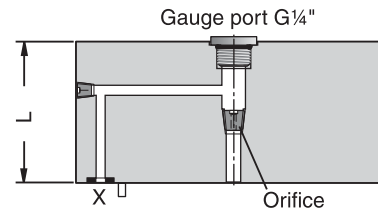

Size	B	L	Orifice Thread
NG16	65.0 (2.56)	36.0 (1.42)	1/16 NPT
NG25	85.0 (3.35)	45.0 (1.77)	1/16 NPT
NG32	102.0 (4.02)	50.0 (1.97)	1/16 NPT
NG40	125.0 (4.92)	60.0 (2.36)	1/8 NPT
NG50	140.0 (5.51)	70.0 (2.76)	1/8 NPT
NG63	180.0 (7.09)	85.0 (3.35)	1/8 NPT
NG80	Ø250.0 (9.84)	105.0 (4.13)	1/8 NPT
NG100	Ø300.0 (11.81)	120.0 (4.72)	1/8 NPT