



Moduflex Valve System

Instant control for all pneumatic actuators,
modular valve islands and stand-alone valves

Catalogue no. PDE2536SLUK September 2015

aerospace
climate control
electromechanical
filtration
fluid & gas handling
hydraulics
pneumatics
process control
sealing & shielding




ENGINEERING YOUR SUCCESS.

Moduflex Valve System: The New Pneumatic Generation


High Performance Technology

Super compact 4/2 slide valve for the best flow to size ratio, reliable long life and short response times.

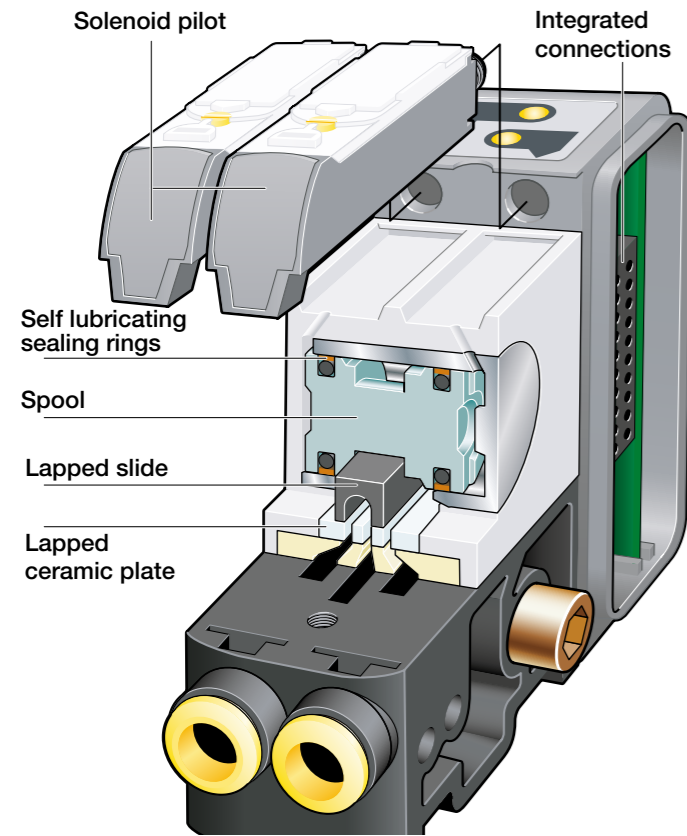


A Complete System

Covering all pneumatic installation requirements with a choice of either stand-alone, short or long valve islands.

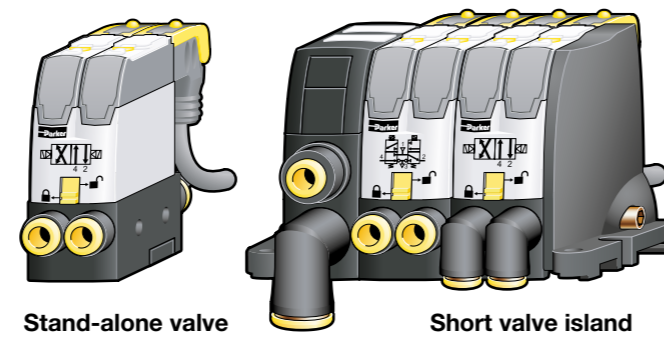


Stand-alone valve Short valve island

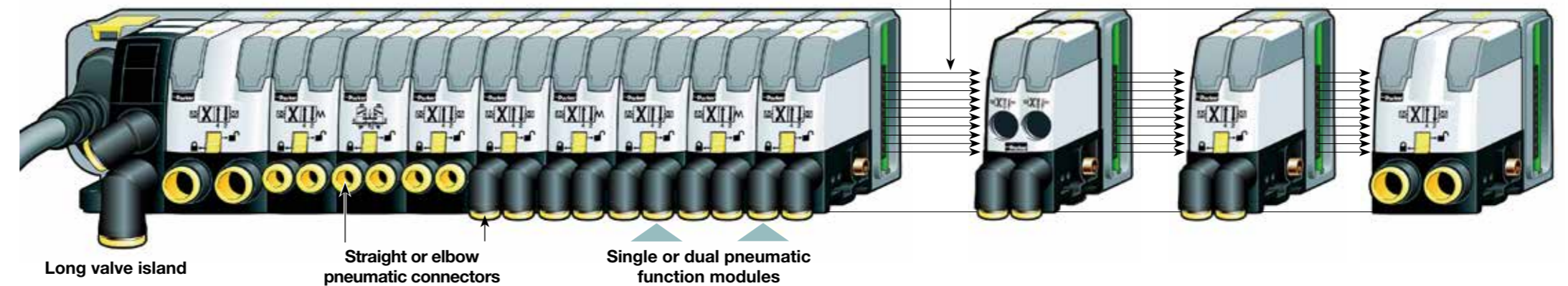

Long valve island Straight or elbow pneumatic connectors Single or dual pneumatic function modules

Individual Connector Valve Islands

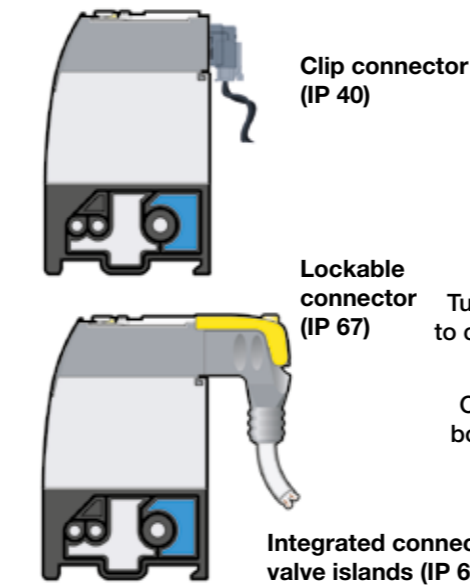

Clip connector (IP 40)

Lockable connector (IP 67)

Tube size to cylinder

Cylinder bore size

3 Valve Sizes Into the Same Valve Island

Size 01	Size 1		Size 2	
Dual 4/2 Sgl Sol 270 NI/mn Section nominal 4mm ²	All functions 400 NI/mn Section nominal 12mm ²		All functions 1200 NI/mn * Section nominal 40mm ²	
Ø ext. 4mm	Ø ext. 4mm	Ø ext. 6mm	Ø ext. 8mm	Ø ext. 10mm
Ø 6 to Ø 25mm	Ø 6 to Ø 25mm	Ø 25 to Ø 40mm	Ø 40 to Ø 63mm	Ø 63 to Ø 100mm

* 2 x 3/2 = 800 NI/min

Pneumatic Specification

- Working pressure of -0.9 to 8 bar

- Flow	Size 01	Size 1	Size 2
Flow channel	7mm ²	12mm ²	40mm ²
Air flow	275 NI/min	400 NI/min ¹⁾	1200 NI/min ¹⁾

¹⁾ 2 x 3/2 = 800 NI/min

- All exhausts are collectable including solenoid pilot exhaust

- 100 million operations with dry or lubricated air 40 µ filtration

Electrical Specification

- Voltage 24V DC. Voltage surge protection

- Non polarity sensitive* (same product for both PNP and NPN)

* Except Pilot Solenoid Valve Clip Connector version

- Protection

Clip connector
Lockable connector

Individual connector IP40
Integrated connections IP65


- Consumption 1W

- Shift time < 10 ms**

** shift time for 4/2 bistable size 1 valve


Easy Man-Machine Dialogue

Diagnostic and manual operations are simple: marking, LED and manual override (MAN) all lined-up with corresponding output to cylinder. Much simpler than with traditional valves.

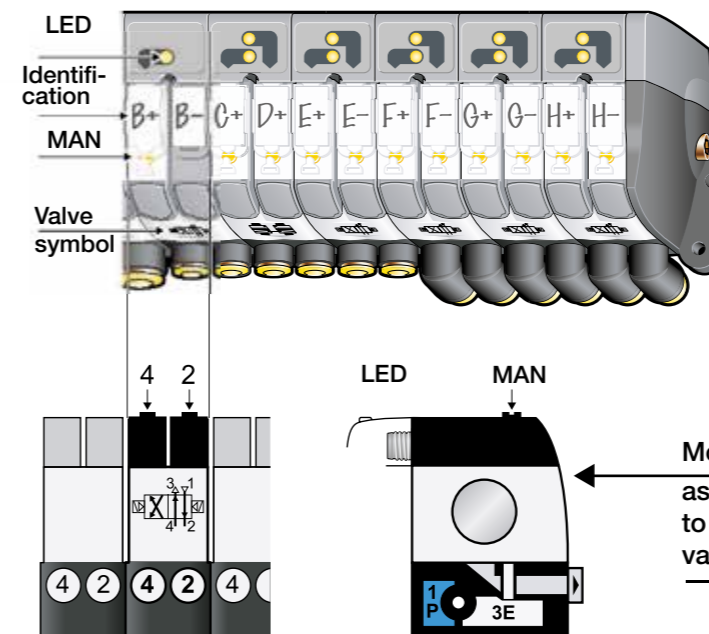

LED MAN

Moduflex as compared to traditional valve island

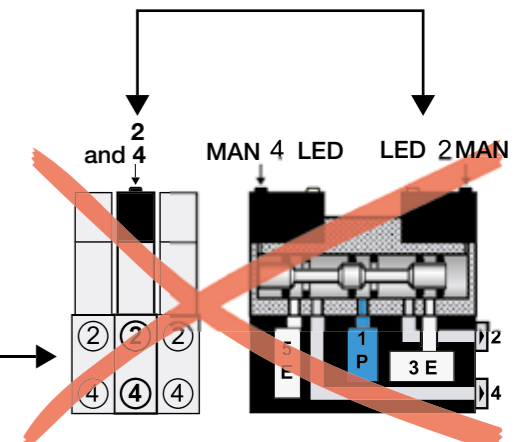


Stand-Alone Modules




Each module is complete with individual connections:

- Pneumatic: pressure supply, exhaust connection and outputs to cylinder
- Electrical: IP67 protected individual connectors

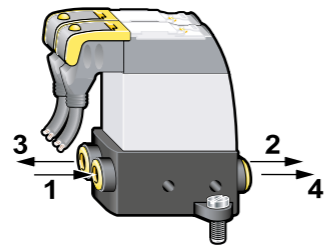


Islands with Individual Connectors

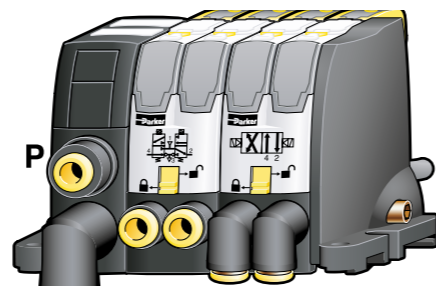


E Short build island

Each module is assembled into an island with a simple modular screw:

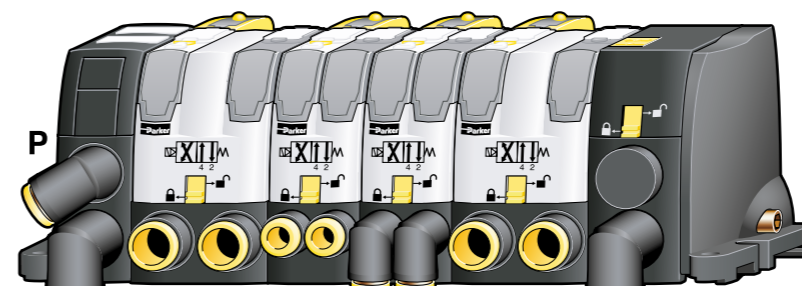

E High flow island

- Remote short build islands require only one pressure supply and one exhaust connection
- Longer high flow islands may require two exhaust connections

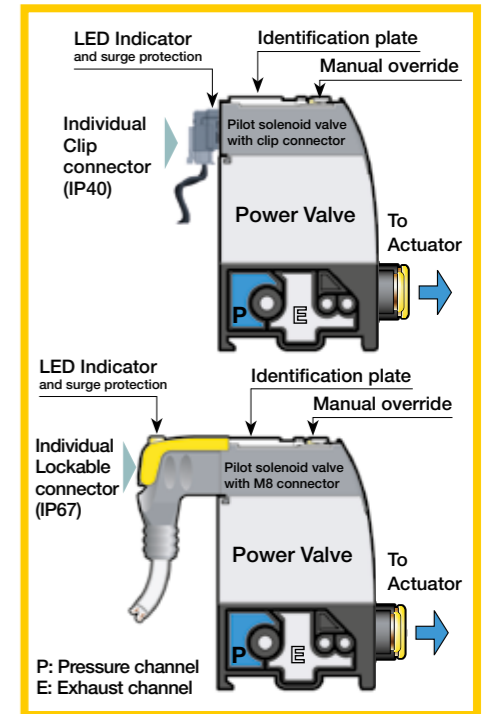





Islands With Integrated Connections

Each module is assembled into an island that includes:


- The pressure and the exhaust channels
- The modular integrated electrical connections

At the head, the island electrical connection is terminated:


- Either with one multi-pin plug-in connector
- Or with a field-bus connection

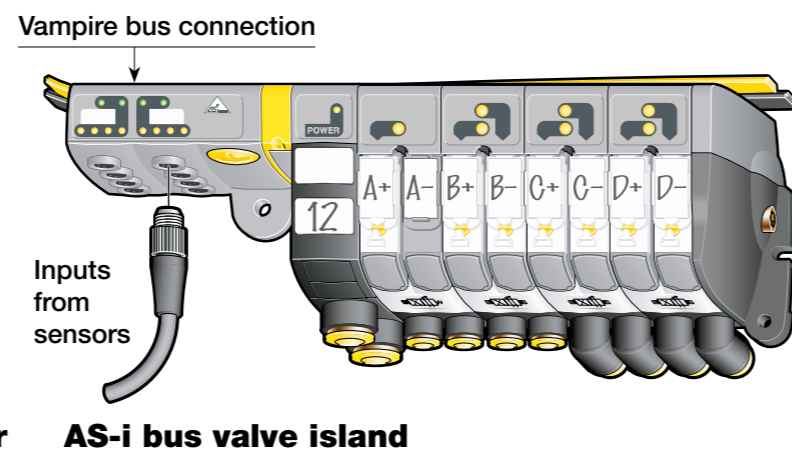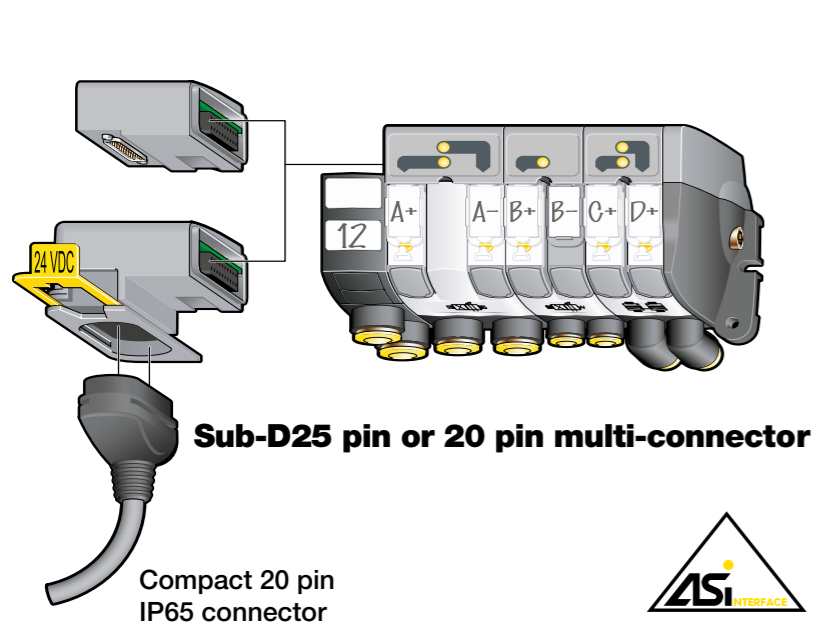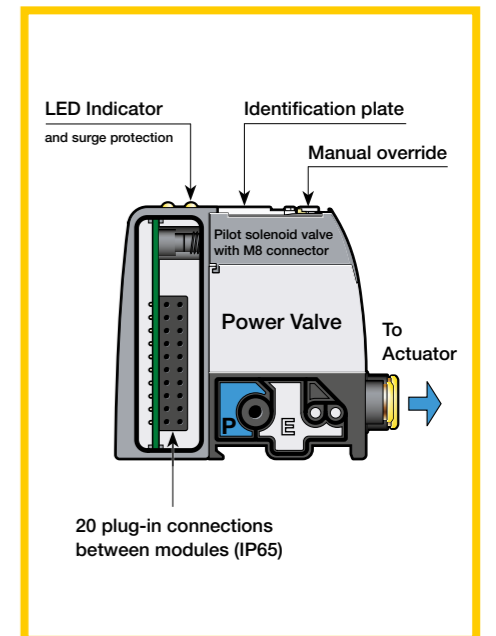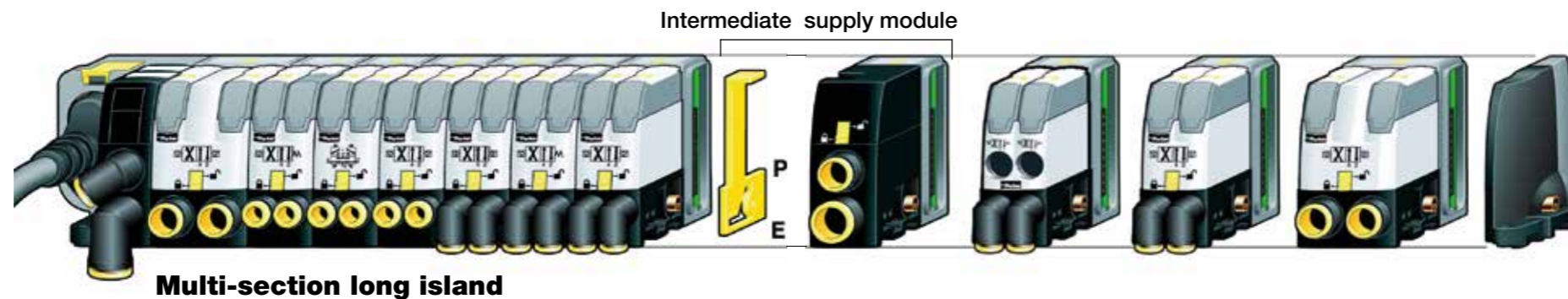


- Standard AS-i protocol (up to 31 nodes)
- AS-i version 2-1 protocol (up to 62 nodes)

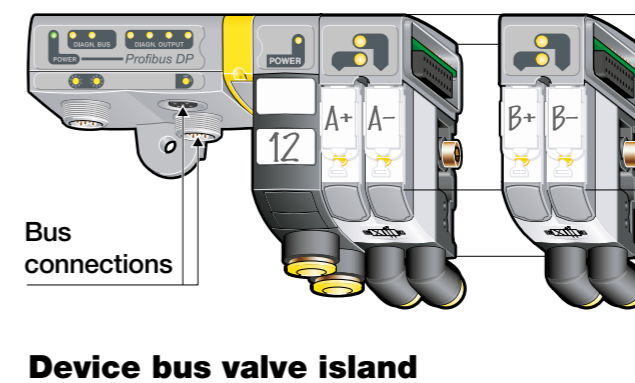

DeviceNet™ PROFIBUS INTERBUS-S
CANopen BUS

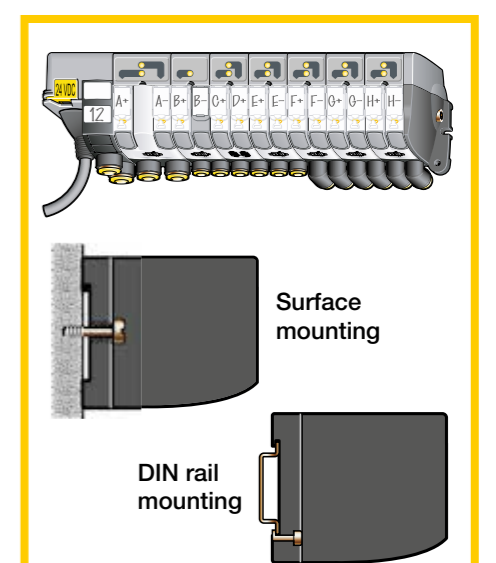


Total Modularity, Total Flexibility...

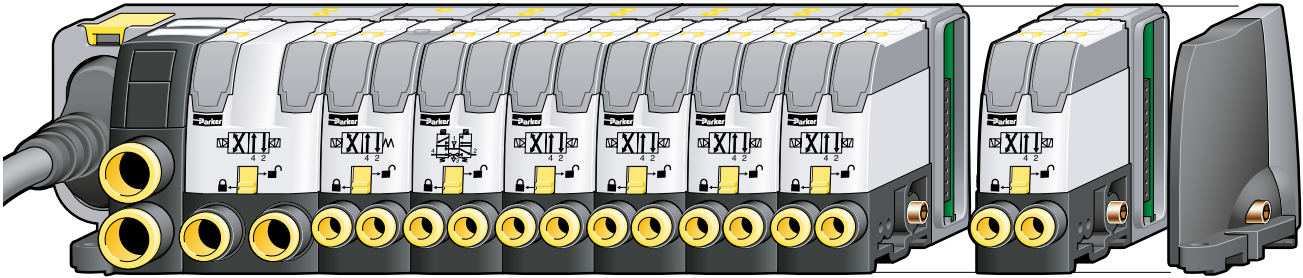

Valve island
internal flexibility



Valve island
peripheral
flexibility

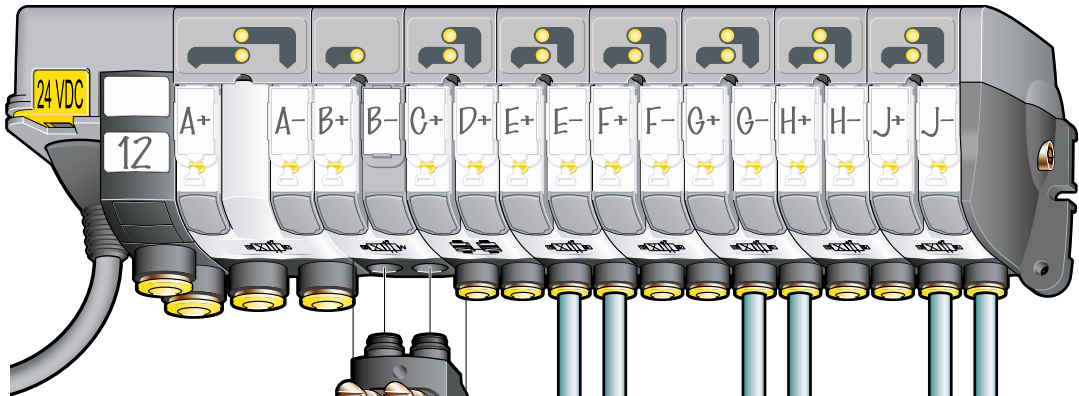

1 Dual flow control module

2 Pressure regulation module

3 Dual pilot operated check valve module

4 Vacuum generator module

Peripheral control modules add flexibility to the valve island. They may be plugged-in directly to the valve island or installed in-line closer to the cylinder or to the vacuum pad.





Moduflex: Valve functions and flow channel




Size 1
12mm² flow channel
400 NI/min ¹⁾

Size 2
40mm² flow channel
1200 NI/min ²⁾



 
2 x 4/2 - way valve
single solenoid

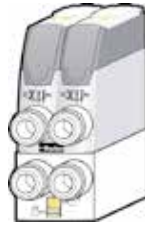


4/2 - way valve
single solenoid

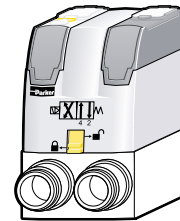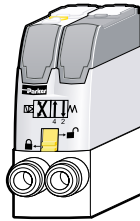 



4/2 - way valve
double solenoid

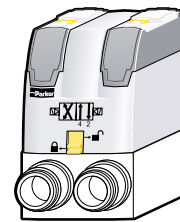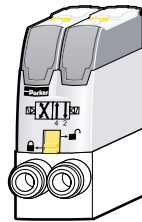 


2 x 3/2 - way valve NC
single solenoid

 



Note: this module can also achieve 3 position functions:
- 3 position vented centre
- 3 position closed centre, with the addition
of a dual pilot operated check valve

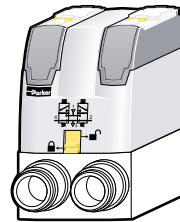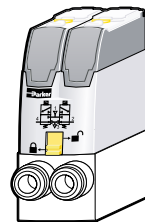

2 x 3/2 - way valve NO
single solenoid

 

Note: this module can also achieve the 3 position
pressure centre function

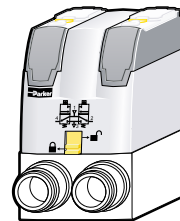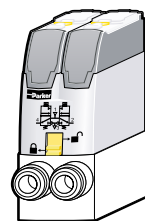

1) 2 x 4/2 = 150 NI/min
2) 2 x 3/2 = 800 NI/min

Parker Worldwide

Europe, Middle East, Africa

AE – United Arab Emirates,
Dubai

Tel: +971 4 8127100
parker.me@parker.com

AT – Austria, Wiener Neustadt
Tel: +43 (0)2622 23501-0
parker.austria@parker.com

AT – Eastern Europe, Wiener
Neustadt
Tel: +43 (0)2622 23501 900
parker.easteurope@parker.com

AZ – Azerbaijan, Baku
Tel: +994 50 2233 458
parker.azerbaijan@parker.com

BE/LU – Belgium, Nivelles
Tel: +32 (0)67 280 900
parker.belgium@parker.com

BG – Bulgaria, Sofia
Tel: +359 2 980 1344
parker.bulgaria@parker.com

BY – Belarus, Minsk
Tel: +375 17 209 9399
parker.belarus@parker.com

CH – Switzerland, Etoy
Tel: +41 (0)21 821 87 00
parker.switzerland@parker.com

CZ – Czech Republic, Klecany
Tel: +420 284 083 111
parker.czechrepublic@parker.com

DE – Germany, Kaarst
Tel: +49 (0)2131 4016 0
parker.germany@parker.com

DK – Denmark, Ballerup
Tel: +45 43 56 04 00
parker.denmark@parker.com

ES – Spain, Madrid
Tel: +34 902 330 001
parker.spain@parker.com

FI – Finland, Vantaa
Tel: +358 (0)20 753 2500
parker.finland@parker.com

FR – France, Contamine s/Arve
Tel: +33 (0)4 50 25 80 25
parker.france@parker.com

GR – Greece, Athens
Tel: +30 210 933 6450
parker.greece@parker.com

HU – Hungary, Budaörs
Tel: +36 23 885 470
parker.hungary@parker.com

IE – Ireland, Dublin
Tel: +353 (0)1 466 6370
parker.ireland@parker.com

IT – Italy, Corsico (MI)
Tel: +39 02 45 19 21
parker.italy@parker.com

KZ – Kazakhstan, Almaty
Tel: +7 7273 561 000
parker.easteurope@parker.com

NL – The Netherlands, Oldenzaal
Tel: +31 (0)541 585 000
parker.nl@parker.com

NO – Norway, Asker
Tel: +47 66 75 34 00
parker.norway@parker.com

PL – Poland, Warsaw
Tel: +48 (0)22 573 24 00
parker.poland@parker.com

PT – Portugal, Leca da Palmeira
Tel: +351 22 999 7360
parker.portugal@parker.com

RO – Romania, Bucharest
Tel: +40 21 252 1382
parker.romania@parker.com

RU – Russia, Moscow
Tel: +7 495 645-2156
parker.russia@parker.com

SE – Sweden, Spånga
Tel: +46 (0)8 59 79 50 00
parker.sweden@parker.com

SL – Slovenia, Novo Mesto
Tel: +386 7 337 6650
parker.slovenia@parker.com

TR – Turkey, Istanbul
Tel: +90 216 4997081
parker.turkey@parker.com

UA – Ukraine, Kiev
Tel: +380 44 494 2731
parker.poland@parker.com

UK – United Kingdom, Warwick
Tel: +44 (0)1926 317 878
parker.uk@parker.com

ZA – South Africa, Kempton Park
Tel: +27 (0)11 961 0700
parker.southafrica@parker.com

North America

CA – Canada, Milton, Ontario
Tel: +1 905 693 3000

US – USA, Cleveland
Tel: +1 216 896 3000

Asia Pacific

AU – Australia, Castle Hill
Tel: +61 (0)2-9634 7777

CN – China, Shanghai
Tel: +86 21 2899 5000

HK – Hong Kong
Tel: +852 2428 8008

IN – India, Mumbai
Tel: +91 22 6513 7081-85

JP – Japan, Tokyo
Tel: +81 (0)3 6408 3901

KR – South Korea, Seoul
Tel: +82 2 559 0400

MY – Malaysia, Shah Alam
Tel: +60 3 7849 0800

NZ – New Zealand, Mt Wellington
Tel: +64 9 574 1744

SG – Singapore
Tel: +65 6887 6300

TH – Thailand, Bangkok
Tel: +662 186 7000

TW – Taiwan, Taipei
Tel: +886 2 2298 8987

South America

AR – Argentina, Buenos Aires
Tel: +54 3327 44 4129

BR – Brazil, Sao Jose dos Campos
Tel: +55 12 4009 3500

CL – Chile, Santiago
Tel: +562 2303 9640

MX – Mexico, Toluca
Tel: +52 72 2275 4200



EMEA Product Information Centre

Free phone: 00 800 27 27 5374

(from AT, BE, CH, CZ, DE, DK, EE, ES, FI, FR, IE, IL,
IS, IT, LU, MT, NL, NO, PL, PT, RU, SE, SK, UK, ZA)

US Product Information Centre

Toll-free number: 1-800-27 27 537

www.parker.com